

Heritage™ 2" Aluminum Blinds

PRODUCT SPECIFICATIONS

SureTight™ Headrail shall be 1-5/8" high x 2-1/4" wide x .022" thick U-shaped steel with 1/8" lightblocking lip on the bottom center line. The steel finishing process includes phosphate treatment for corrosion resistance, a chrome-free sealer, a low hazardous air pollutants (HAP) urethane primer, and a topcoat of low HAP, polyester-baked enamel.

Tilter shall be a snap-in component incorporating a worm and pulley of low-friction thermoplastic and a nylon gear. Tilt cords shall measure 1.8 mm diameter.

Tilt Rod shall be electro-zinc coated solid steel measuring 1/4" square.

Tilt Wand shall be clear polycarbonate with a hexagonal cross section measuring approximately 5/16" diameter and attached to the tilter shaft by means of a spring clip for easy removal.

Lift Cord is available in 1.8 mm.

Cordlock shall be metal of a snap-in design incorporating a floating, shaft-type locking pin and shall incorporate a crash-proof safety feature that will lock blind automatically upon release of cord.

Drums shall be made of high-strength thermoplastic, which securely anchors braided ladders.

Installation Brackets shall be made of phosphate-treated steel with a urethane primer and polyester-baked enamel finish to match headrail. The design shall incorporate a hinged front cover.


Braided Ladder shall be made of 100% polyester yarn, incorporating two extra-strength rungs per ladder for slat support. Standard ladder spacing shall be 44 mm.

Slats shall be 5000 series cold-rolled aluminum containing the maximum allowable recycled content to produce a high-strength and corrosion-resistant flexible product. Slats shall be nominally 2" wide x .008" thick and processed to provide a smooth, hard, less porous surface with antistatic performance to repel dust. Slats shall be treated with a topcoat of low HAP polyester-baked enamel.

Bottomrail shall be C-shaped 9/16" high x 2" wide x 0.40" thick anodized aluminum. It shall be fully enclosed with a dust cover slat and finished with a polyester-baked enamel to match headrail.

OPTIONS

- 1" or 1-1/2" FR rated cloth tapes
- Inverted slat for daylighting
- Cord tilt
- Ring tilt
- Motorized – tilt only
- Ring pull
- Extension brackets
- Hold down brackets
- Cut-outs
- Deluxe channel panel valance
- Custom cord lengths available

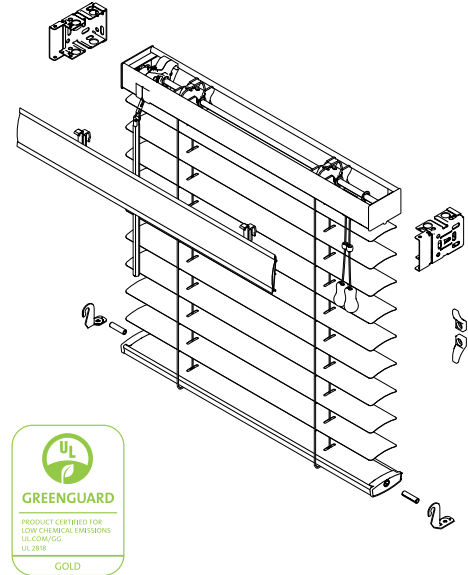

PRODUCT FEATURES AND BENEFITS

- Ideal for large window applications
- 1-5/8" x 2-1/4" SureTight heavy-duty steel headrail
- Lightblocking lip on headrail eliminates light leakage
- Enclosed bottomrail
- Box bracket
- Compliant with ANSI WCMA A100.1-2018 standard for cord length
- Antistatic performance to repel dust
- Low HAP, low VOC paint process
- Slats meet NFPA 701
- GREENGUARD Gold certified
- Limited lifetime warranty

*Identical to Bali® Heritage™
2" Aluminum Blinds*