



R-Series Fascia Brackets

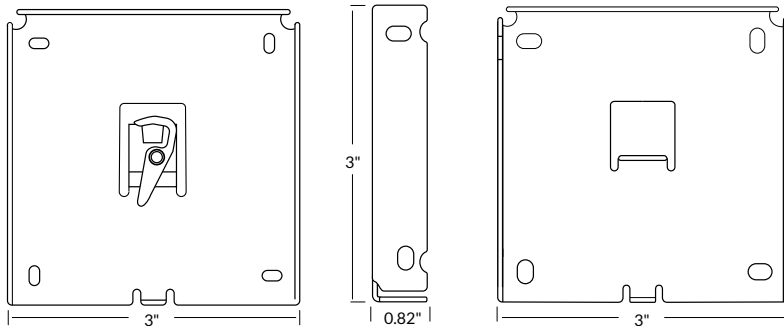


3" Fascia R8 Bracket

- Part# 39-5059-xx
- 3" x 3"
- 2.585" maximum roll diameter
- Overhead, wall or jamb mount
- Black, White, Vanilla or Gray

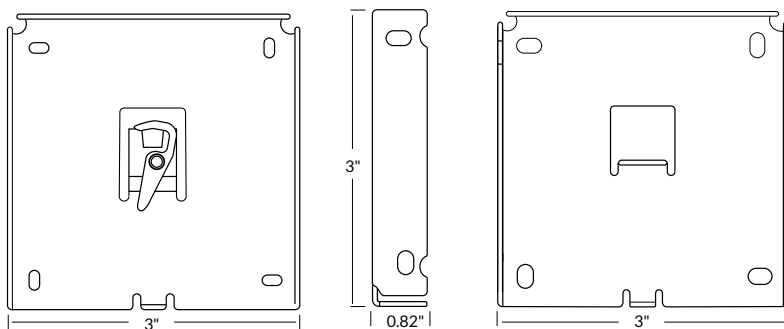

3" Fascia R16 Bracket

- Part# 39-5060-xx
- 3" x 3"
- 3.585" maximum roll diameter
- Overhead, wall or jamb mount
- Black, White, Vanilla or Gray
- Manual shade bracket only

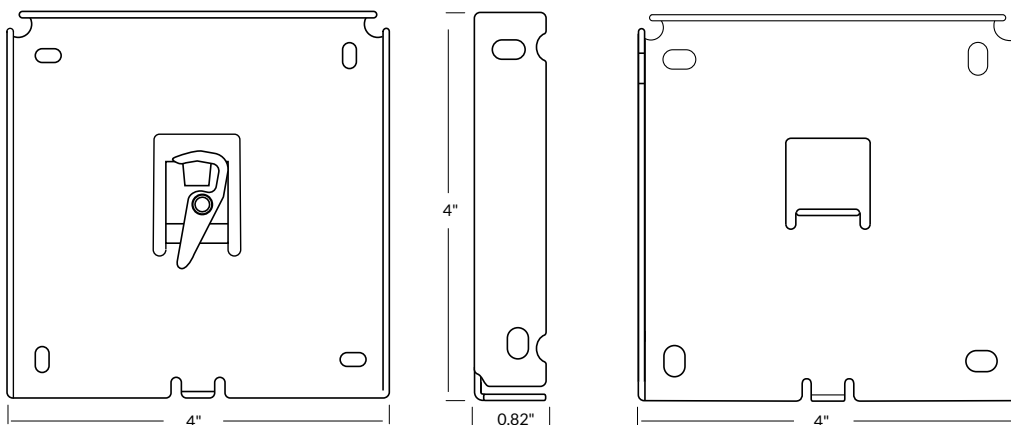

4" Fascia R16/R24 Bracket

- Part# 39-5061-xx
- 4" x 4"
- 3.585" maximum roll diameter
- Overhead, wall or jamb mount
- Black, White, Vanilla or Gray
- Manual shade bracket only