


R-Series No Fascia Brackets

R8 Bracket

- Part# 39-0012-xx
- 1.5" x 2"
- 3.515" maximum roll diameter
- Overhead, wall or jamb mount
- Black or White

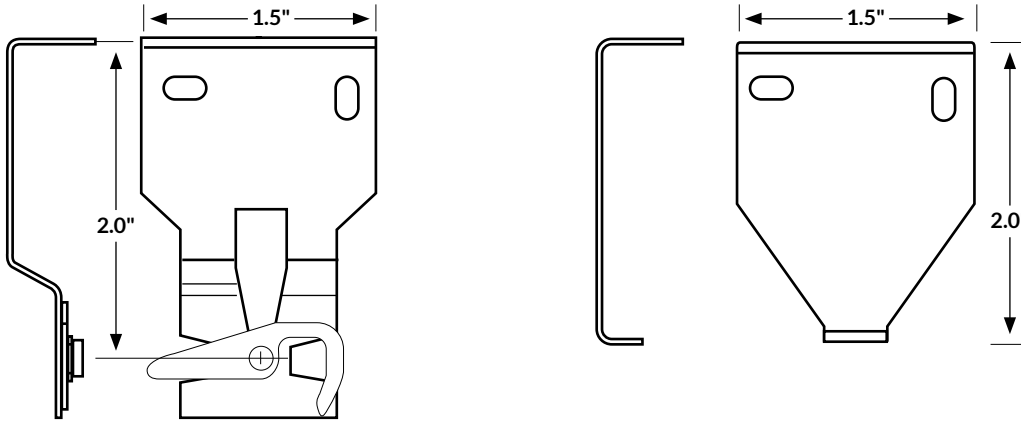

R16/24 Brackets

- Part# 39-0013-xx
- 2.5" x 2.25"
- 3.765" maximum roll diameter
- Overhead, wall or jamb mount
- Black or White
- Manual Shade bracket only

