


IGC 4n1 Motor Controller

The Individual Group Control (IGC) 4n1 Motor Controller provides individual and group control for up to four Somfy® Wired Technology (Standard WT) motors with up to three intermediate positions per motor. Through the use of the DecoFlex Dry Contact Keypad (#39-5533-01, required), users can access 3 preset positions as well as Up, Down and Stop. Keypads can also be used to set custom intermediate positions. Multiple IGC 4n1 Motor Controllers can be daisy-chained together for simplified synchronized control from a single keypad. The IGC 4n1 Motor Controller can not set upper and lower motor limits, but senses the current to identify them.

PART NUMBER: 15832-00

TECHNICAL SPECIFICATIONS

- Line Voltage Input:
120 V AC +/- 10%; 50-60Hz
- Low Voltage Output to Keypads:
12V DC 185 mA maximum consumption
- Output to Motor:
120V AC (5A per motor) ¼ HP
- Fuses:
5x5A (1 for each motor, 1 for the board)
- Material: Steel
- CSA / UL certified
- Weight: 10 lbs.
- Indoor use only
- Plenum Rated: Yes

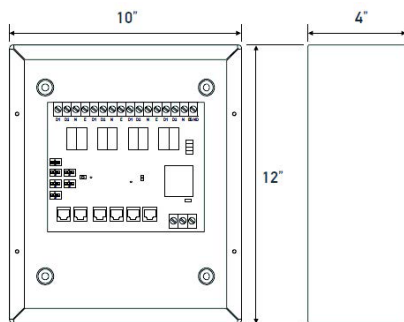


PRODUCT FEATURES AND BENEFITS

- Control up to four Standard WT motors individually or in groups.
- Provides default intermediate positions of 25%, 50%, and
- 75% openness which can also be customized for each motor.
- Individual control and Master control using DecoFlex Dry
- Contact Keypads.
- Integration via dry contact relays
- Four Keypad ports and two Master ports.
- CSA/UL certified.
- Plenum rated.



IGC 4n1 Motor Controller

CONNECTIONS AND INDICATORS

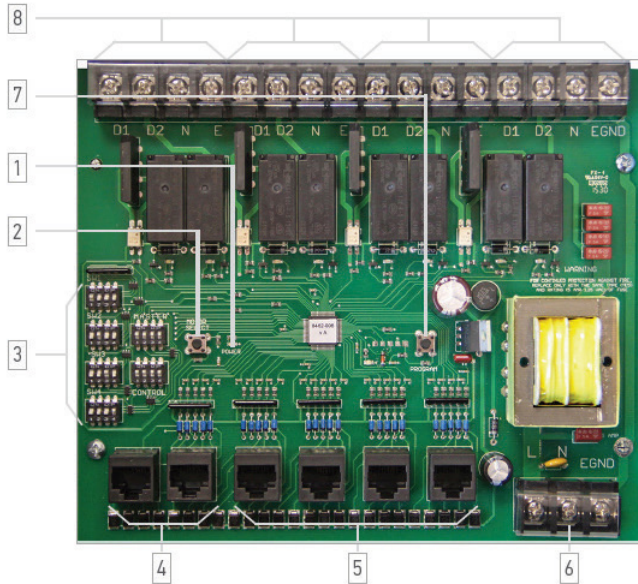

Element		Funtion
1	Power LED	Indicates power is on
2	Motor Selector Button	Sets Keypad group
3	Dip Switches	Motor Selection
4	Master Ports	Connect Master Keypads and Daisy Chain Controllers
5	Individual Motor Key Ports	Connect Keypads for each group
6	To 110V AC	Connect to Power
7	Program Button	Set
8	To Motors	Connect to Motors

PRODUCT FEATURES AND BENEFITS

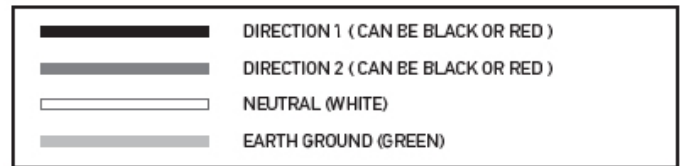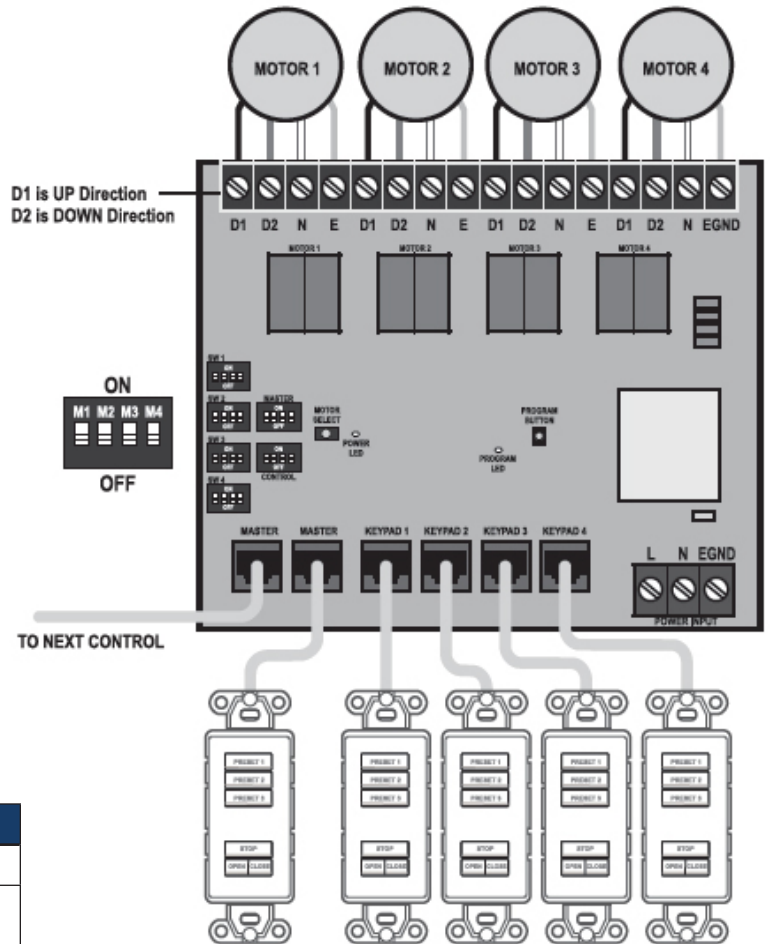

CAT 5e Pinout

