


Motorized Shade Edge Gaps

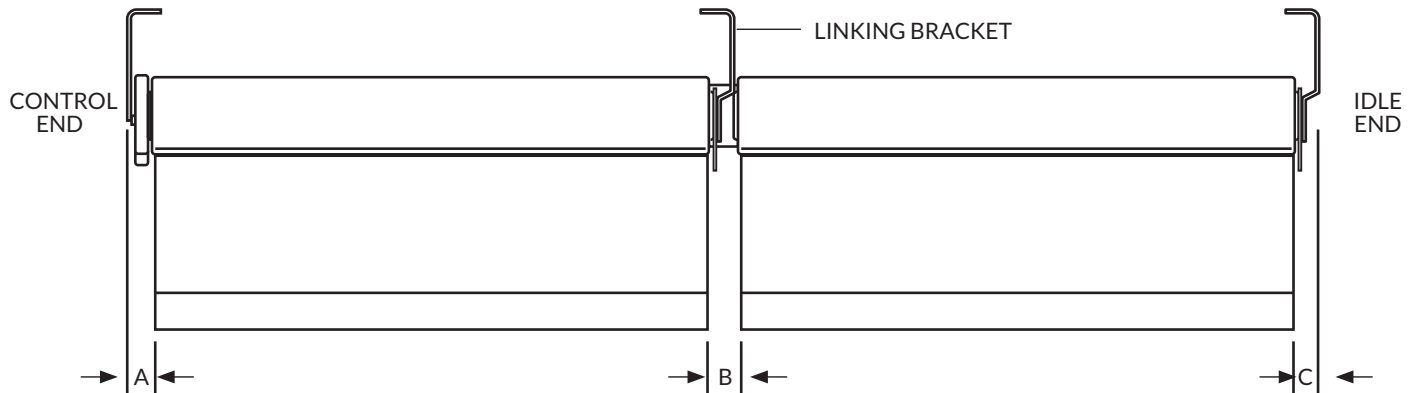

| Bracket | A: Control End | B: Linking Bracket | C: Idle End |
|----------------------------|----------------|--------------------|-------------|
| R28 with 11/2" tube | 11/16" | 3/4" | 7/16" |
| Soness® 30 with 11/2" tube | 11/16" | 3/4" | 1/2" |
| Standard | 15/16" | 1-1/8" | 13/16" |
| Standard with fascia | 1-3/16" | 1-1/8" | 13/16" |
| Extended | 1-1/8" | 1-1/8" | 13/16" |
| Extended with fascia | 1-1/8" | 1-1/8" | 13/16" |
| Heavy duty | 1-13/16" | n/a | 1-11/16" |

- Motorized shade measures should be from outside of bracket to outside of bracket.
- Inside mount and outside mount have the same deductions.
- Inside mount has an additional 1/8" deduction on fascia only.