


12V DC / 24V DC Power Options

PLUG-IN

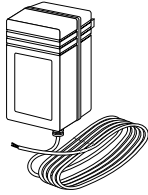


WALL TYPE

# OF MOTORS	DIMENSIONS	NOMINAL LOAD	PART NUMBER
1 Motor	2.875"H x 1.75"W x 1.5"D	24V DC 1.25A	39-5124-00


WIRE-FREE POWER OPTIONS




12V DC Reloadable Battery Tube (batteries not included) 95-1517-00

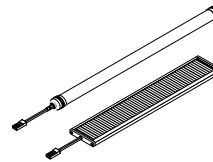


Solar Pack 15815-00

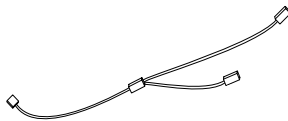


Dual Reloadable Battery Tube (harness only) to connect two reloadable battery tubes 95-1532-00

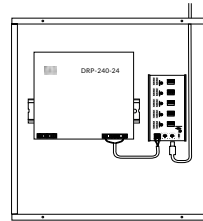


12V DC 10 Motor Power Kit 39-5454-00
Voltage output: 12V DC
Voltage input: 85-110V AC
3.3 amps

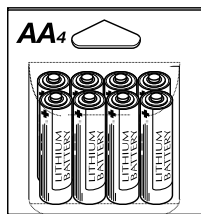


8 AA Energizer Lithium Battery package 95-1518-00

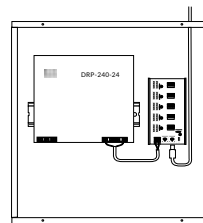

 24V DC 5 Motor Power Kit 39-5452-00
Voltage output: 24V DC
Voltage input: 85-110V AC
3.5 amps



12V DC Plug-in Transformer with 6 ft cable (white) 95-1533-00

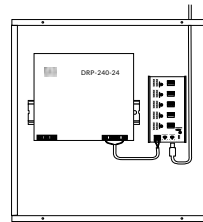

24V DC 10 Motor Power Kit 39-5453-00
Voltage output: 24V DC
Voltage input: 85-110V AC
4.8 amps

