



# Standard Motorized No-Fascia Brackets

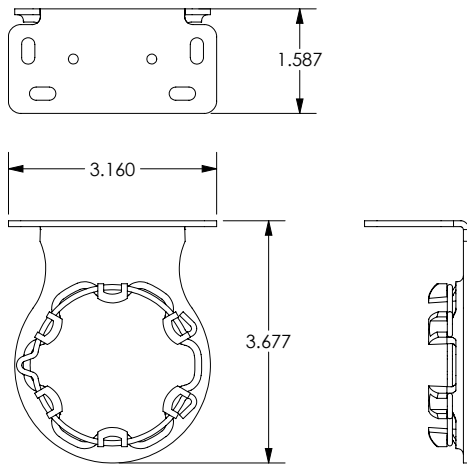


**Drive Bracket**  
**# 39-5188-xx**

- 3.16" x 3.677"
- 3.675" maximum roll diameter
- Overhead or wall mount
- Black or White

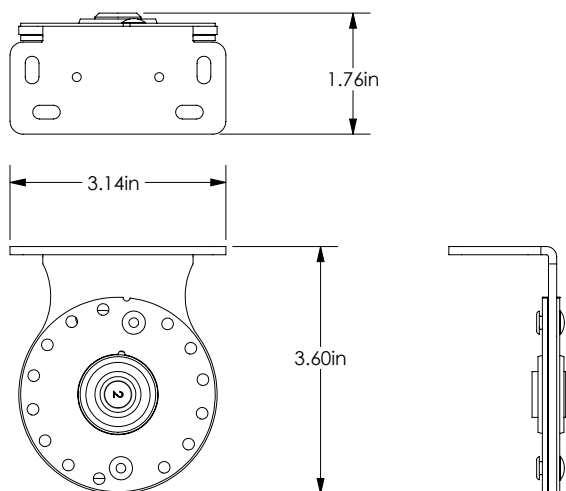

**Idle Bracket**  
**# 39-5545-xx, 39-5546-xx**

- 3.14" x 3.6"
- 3.675" maximum roll diameter
- Overhead or wall mount
- Black or White

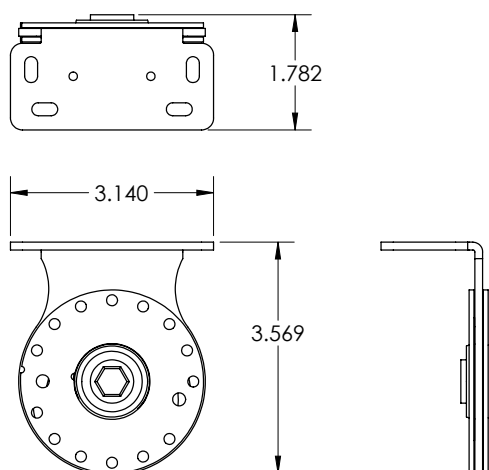

**Intermediate Bracket**  
**# 39-5019-xx, 39-5021-xx**

- 3.14" x 3.569"
- 3.675" maximum roll diameter
- Overhead or wall mount
- Black or White