



Features

- Thermally broken lid and upstand
- External curb liner
- 75mm polyisocyanurate board (0.26 W/m2K)
- Slam latch with internal and external handles
- Padlockable internal and external
- Any colour available



Standard Specification



Material

Cover and frame 2mm aluminium
75mm thermally broken composite lid and upstand.
Aluminium extrusion grade 6063T6
Aluminium sheet grade 1050

Cover

75mm (3") fully insulated kerb and lid, corner welded and reinforced.

Upstand

300mm upstand with external curb liner.
Thermally broken with 75mm insulation and 117mm fixing flange.
Integral weathering lip.

Insulation

75mm Polyisocyanurate (PIR) insulation to 0.26 W/m²K U-value.

Seal

Double unbroken bubble & blade seal to lid.

Operation

Gas spring assisted opening.

Hinge

Heavy duty continuous hinge.

Locking

Heavy duty stainless steel slam latch (LO1)
Internal hasp & staple for padlock (LO2)
External padlockable handle (LO4)
(Padlocks by others)
Hold open safety stay

Finish

Mill finish aluminium

Product Codes	Standard Sizes*	Weights
SRHP75/60.60	600 x 600	36kg
SRHP75/75.75	750 x 750	44kg
SRHP75/75.90	750 x 900	49kg
SRHP75/90.90	900 x 900	54kg
SRHP75/100.100	1000 x 1000	60kg
SRHP75/150.75	1500 x 750	70kg
SRHP75/120.120	1200 x 1200	105kg

*Bespoke sizes available

Testing



 
Resistance to wind loads (Class A4)



Weatherproof (Class A7)



Tested to Air Permeability (Class A4)




Water Ingress Test Water & Solid IPX6 (UKAS)




Dust Ingress Test IP6X (UKAS)



Ingress Protection Water & Solid

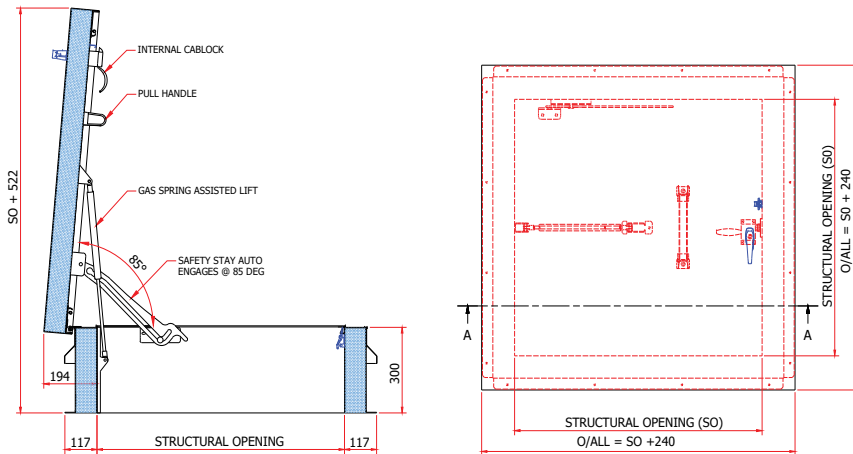

WATCH OUR
INSTALL VIDEO

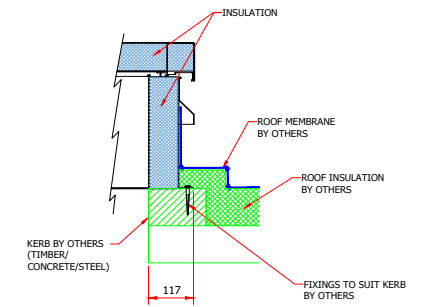

Typical Install

Options

Free of Charge:



Non-Combustible
Mineral Wool Insulation




Wind Restraint

Locking:



LO6 European
Deadlock. Int
Thumb Turn, Ext Key

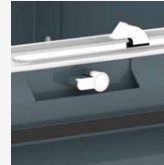


LO7 European
Deadlock Int/Ext
Key Lock

Other Options:

- Electric Opening
- Concealed Actuator
- Fire Rated up to 4 hours
- Acoustic Rating up to 45dB
- Walk On Top
- Pitched Roof Installation
- Extended Cap & Flashing
- Single or twin polyester powder coating

Ladder-Up Post

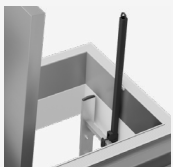


Sureguard Handrail



Fixed Handhold



Safety Grid

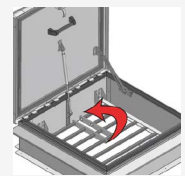

Ladder Arrangements

ZIP Retractable Ladders



Roof Hatch + ZIP Ladder

Fixed Vertical Ladders



Roof Hatch + Vertical Ladder

Companionway



Roof Hatch + Companionway Ladder