



Dual Vertical Lift Gate

The Dual Vertical Lift Gate provides wide coverage against falls while maintaining a height clearance. Gas struts make for easy operation and the gate is perfect for loading docks, mezzanines, or any large coverage areas. Locking feature provides safety from any push or pull resistance while exceeding 200lb of protection.


The Dual Vertical Lift gate is available in 8' and 10' width coverage.

**Available in safety yellow powder coating and custom orders.
Takes up minimal space and is easy to install using basic tools.
Meets or exceeds OSHA 1910.23 (c) standards**

Determining the proper gate size for your application only requires the measurement of the inside clear opening.

Carbon Steel with Safety Yellow Powder Coat

Model No.	Fits Clear Opening	Est. Weight	Opening Clearance
DVG15 - 120PC	8'	130 lbs	12 ft
DVG15 - 144PC	10'	140 lbs	15 ft

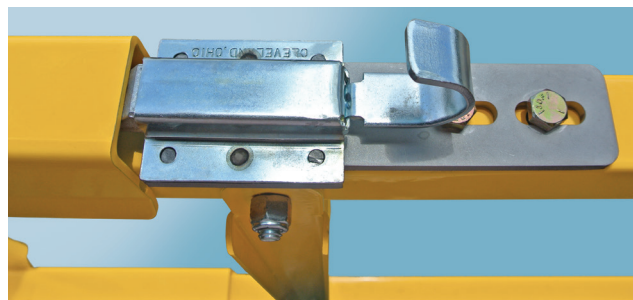

Safety Lock Mechanism, and Gas Struts for ease of operation

The standard sizes listed above are stock items. FabEnCo also manufactures custom safety gates for wider openings or unusual handrail configurations. Please contact us with your special requirements.